


# Suction cup with connector OGVM-20X60-GV-N-RA

Part number: 8213250

**FESTO**

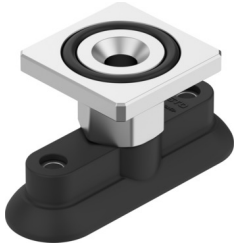

## Data sheet

Feature	Value
Suction cup height compensation	5 mm
Min. workpiece radius	12.5 mm
Nominal width	6 mm
Vacuum cup size	20x60 mm
Suction cup volume	5 cm <sup>3</sup>
Connection position	Top
Mounting position	Any
Suction cup shape	Oval, bell-shaped
Operating pressure	-95 kPa...0 kPa -0.95 bar...0 bar -13.775 psi...0 psi
Nominal operating pressure	-60 kPa -0.6 bar -8.7 psi
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:::-]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-A1/A2-L
Ambient temperature	-20 °C...80 °C
Holding force at nominal operating pressure	81 N
Vertical lateral force at nominal operating pressure	103 N
Product weight	27 g
Type of mounting	Via vacuum connection
Vacuum connection	Rectangular adapter RA
Color	Black
Shore hardness	60 +/- 5
Material of screwed plug	Wrought aluminum alloy
Note on materials	RoHS-compliant
Suction cup material	NBR