


# Parallel kit EAMM-U-145-C68-16-138C-188-S5

Part number: 8216603

FESTO

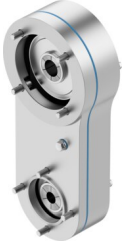

## Data sheet

Feature	Value
Size	145
Mounting position	Any
Gear ratio	1:1
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 100 %
Degree of protection	IP69K
Ambient temperature	-10 °C...60 °C
Mass moment of inertia	2221 kgmm <sup>2</sup>
Transferable torque	50 Nm
Product weight	10600 g
Interface code, actuator	C68-16
Interface code, motor in	138C
Note on materials	RoHS-compliant