 



Kištukas SEA-3GS-M8-S

Gaminio numeris: 192009

FESTO

Skirstytuvų saloms.

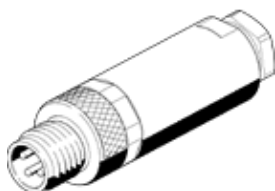

Tech. Duomenys

Savybės	Reikšmė
Atitinka standartus	EN 61076-2-104 EN 61984
Montavimo pozicija	Bet koks
Produkto svoris	6 g
Dėžės dydis	1
Electrical connection 1, design	apvalus
Electrical connection 1, connection type	Kištukas
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	M8x1, A-coded to EN 61076-2-104
Electrical connection 1, number of pins/wires	3
Electrical connection 1, type of mounting	Screw-type lock with hexagon A/F 9 mm and longitudinal knurl
Electrical connection 2, function	Controller side
Electrical connection 2, connection technology	Įsuktas terminalas
Electrical connection 2, number of pins/wires	8
Nominalus DC įtampos lygis	≤ 60 V
Nominalus AC įtampos lygis	≤ 60 V
Leistina srovės apkrova prie 40°C	3 A
Atsparumas smūgiams	1,5 kV
Kabelio prijungimas	Pg7
Kabelio skersmuo	2,5 ... 5 mm
Nominalus laidininko skerspjūvis	0,14 ... 0,5 mm ²
Apsaugos klasė	IP65
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	-40 ... 85 °C
CE ženklas (žr. deklaraciją)	atitinka EU reikalavimus žemose įtampose
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS
Užterštumo laipsnis	3
Atsparumo korozijai klasė CRC	1 - Low corrosion stress
Material housing	PA
Korpuso spalva	Juodas
Material screw-type lock	Nickel-plated die-cast zinc
Material seals	NBR
Material electrical contact	Brass, gold-plated