 



EMC-filter CAMF-C5-FC

Gaminio numeris: 4825847
Nebetiekiamas produktas

FESTO

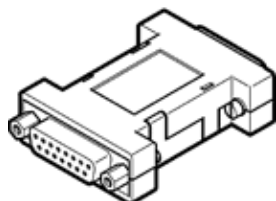

Tech. Duomenys

| Savybės | Reikšmė |
|--|------------------------|
| Nominalus DC įtampos lygis | 0 ... 30 V |
| Nominali darbinė nuolatinė įtampa | 24 V |
| Nominalus AC įtampos lygis | 0 ... 30 V |
| Nominali darbinė kintama įtampa | 24 V |
| PWIS conformity | VDMA24364-B2-L |
| Apsaugos klasė | IP30 |
| Note on degree of protection | Sumontuotas |
| Aplinkos temperatūra | -40 ... 80 °C |
| Informacija | atitinka RoHS |
| Electrical connection 1, function | Field device side |
| Electrical connection 1, design | kampinis |
| Electrical connection 1, connection type | Kištukų lizdas |
| Electrical connection 1, cable outlet | Tiesus |
| Electrical connection 1, connection technology | Sub-D |
| Electrical connection 1, number of pins/wires | 15 |
| Electrical connection 1, occupied pins/wires | 8 |
| Electrical connection 2, function | Controller side |
| Electrical connection 2, design | kampinis |
| Electrical connection 2, connection type | Kištukas |
| Electrical connection 2, cable outlet | Tiesus |
| Electrical connection 2, connection technology | Sub-D |
| Electrical connection 2, number of pins/wires | 15 |
| Electrical connection 2, occupied pins/wires | 8 |
| Electrical connection 2, type of mounting | 2x screw 4-40 UNC-2A |
| Protokolas | HIPERFACE |
| Korpuso spalva | sidabrinis |
| Material housing | Metalizuotas polimeras |