
 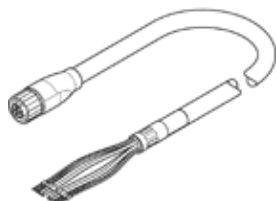


Variklio kabelis

NEBM-M16G8-E-20-Q7-LE8

Gaminio numeris: 5085049
Nebetiekiamas produktas

FESTO



Tech. Duomenys

| Savybės | Reikšmė |
|--|--|
| Paremtas standartu | EN 61984 |
| Cable identification | Without inscription label holder |
| Electrical connection 1, function | Field device side |
| Electrical connection 1, design | apvalus |
| Electrical connection 1, connection type | Kištuko lizdas |
| Electrical connection 1, cable outlet | Tiesus |
| Electrical connection 1, connection technology | M16x0,75 |
| Electrical connection 1, number of pins/wires | 8 |
| Electrical connection 1, occupied pins/wires | 6 |
| Electrical connection 2, function | Controller side |
| Electrical connection 2, connection type | Kabelis |
| Electrical connection 2, connection technology | atviri laidai |
| Electrical connection 2, number of pins/wires | 8 |
| Electrical connection 2, occupied pins/wires | 6 |
| Nominalus DC įtampos lygis | 0 ... 600 V |
| Note on operating voltage range DC | 0 - 300 V for 0.25 mm ² |
| Nominalus AC įtampos lygis | 0 ... 600 V |
| Note on operating voltage range AC | 0 - 300 V for 0.25 mm ² |
| Leistina srovės apkrova prie 40°C | 12 A |
| Note on acceptable current load at 40°C | 4 A for 0.25 mm ² |
| Atsparumas smūgiams | 6 kV |
| Note on surge resistance | 4 kV for 0.25 mm ² |
| Kabelio ilgis | 20 m |
| Kabelio priedas | Suitable for energy chains |
| Bending radius, fixed cable installation | ≥ 55 mm |
| Bending radius, flexible cable installation | ≥ 110 mm |
| Kabelio skersmuo | 11 mm |
| Kabelio struktūra | 4x0,75+2x(2x0,25) Ekranuotas |
| Nominalus laidininko skerspjūvis | 0,25 mm ² 0,75 mm ² |
| Laido galai | Laido antgalis |
| Apsaugos klasė | IP65 |
| Note on degree of protection | Sumontuotas |
| Aplinkos temperatūra | -50 ... 90 °C |
| Aplinkos temperatūra esant lankščiai kabelių instaliacijai | -40 ... 90 °C |
| CE ženklas (žr. deklaraciją) | atitinka EU reikalavimus žemose įtampose in accordance with EU RoHS directive |
| UKCA marking (see declaration of conformity) | To UK instructions for electrical equipment To UK RoHS instructions |
| PWIS conformity | VDMA24364-B2-L |
| Informacija | atitinka RoHS |
| Užterštumo laipsnis | 3 |
| Atsparumo korozijai klasė CRC | 0 - No corrosion stress |
| Material cable sheath | TPE-U(PUR) |
| Kabelio apvalkalo spalva | oranžinis |
| Material insulation | TPE-E |