

 

Kabelis

NEBV-M12G8-KD-3-M12G4

Gaminio numeris: 547888

FESTO

Proporciniam slėgio reguliatoriui VPPM.

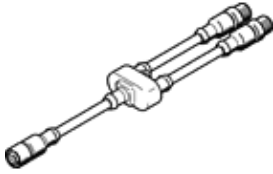

Tech. Duomenys

Savybės	Reikšmė
Atitinka standartus	DIN 47100 EN 61076-2-101
Konstrukcija	Y-distributor with cables on both sides
Distributor type	1 to 2
Papildomos funkcijos	Distribution of the analogue inputs and outputs of a proportional pressure regulator
Cable identification	Without inscription label holder
Montavimo tipas	With through-hole for M3 screw
Electrical connection 1, function	Field device side
Electrical connection 1, design	apvalus
Electrical connection 1, connection type	Kištuko lizdas
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 1, number of pins/wires	8
Electrical connection 1, occupied pins/wires	5
Electrical connection 1, type of mounting	Screw lock
Electrical connection 2, function	Controller side
Electrical connection 2, design	apvalus
Electrical connection 2, connection type	Kištukas
Electrical connection 2, cable outlet	Tiesus
Electrical connection 2, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 2, number of pins/wires	4
Electrical connection 2, occupied pins/wires	4
Electrical connection 2, type of mounting	Screw lock
Electrical connection 3, function	Controller side
Electrical connection 3, design	apvalus
Electrical connection 3, connection type	Kištukas
Electrical connection 3, cable outlet	Tiesus
Electrical connection 3, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 3, number of pins/wires	4
Electrical connection 3, occupied pins/wires	3
Electrical connection 3, type of mounting	Screw lock
Nominalus DC įtampos lygis	0 ... 30 V
Nominalus AC įtampos lygis	0 ... 30 V
Leistina srovės apkrova prie 40°C	2 A
Atsparumas smūgiams	0,8 kV
Cable length 1	2,5 m
Cable length 2	0,5 m
Kabelio priedas	Standartas
Bending radius 1, fixed cable installation	≥ 33 mm
Minimum bending radius with freely moveable use 1	≥ 66 mm
Bending radius 2, fixed cable installation	≥ 33 mm
Minimum bending radius with freely moveable use 2	≥ 66 mm
Cable diameter 1	6,3 mm

Savybės	Reikšmė
Tolerance for cable diameter 1	± 0,2 mm
Cable diameter 2	6,3 mm
Tolerance for cable diameter 2	± 0,2 mm
Kabelio struktūra	8x0,25 Ekranuotas
Nominalus laidininko skerspjūvis	0,25 mm ²
Apsaugos klasė	IP67
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	-25 ... 80 °C
Aplinkos temperatūra esant lankščiai kabelių instaliacijai	-5 ... 80 °C
CE ženklas (žr. deklaraciją)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS Be halogeno
Užterštumo laipsnis	3
Atsparumo korozijai klasė CRC	2 - Moderate corrosion stress
Material cable sheath	TPE-U(PUR)
Kabelio apvalkalo spalva	pilkas
Material housing	TPE-U(PUR)
Korpuso spalva	Juodas
Material screw-type lock	Nickel-plated brass
Material seals	NBR
Material electrical contact	Nickel-plated and gold-plated brass
Material insulation	PP