


# Jungtis su kabeliu NEBV-H1G2-P-0.5-N-LE2

Gaminio numeris: 566658

★ Kernprogramm

FESTO

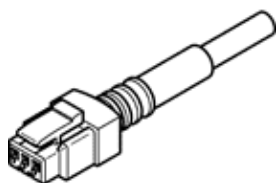

## Tech. Duomenys

Savybės	Reikšmė
Cable identification	Without inscription label holder
Montavimo pozicija	Bet koks
Produkto svoris	8 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	kampinis
Electrical connection 1, connection type	Kištuko lizdas
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	Connection pattern H
Electrical connection 1, number of pins/wires	3
Electrical connection 1, occupied pins/wires	2
Electrical connection 1, type of mounting	Snap-in locking
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Kabelis
Electrical connection 2, connection technology	atviri laidai
Electrical connection 2, number of pins/wires	2
Electrical connection 2, occupied pins/wires	2
Nominalus DC įtampos lygis	0 ... 60 V
Leistina srovės apkrova prie 40°C	3 A
Kabelio ilgis	0,5 m
Kabelio priedas	Statiniam panaudojimui
Kabelio skersmuo	3,4 mm
Kabelio struktūra	2x0,14
Nominalus laidininko skerspjūvis	0,14 mm <sup>2</sup>
Laido galai	Sheath removed Cut off bluntly
Apsaugos klasė	IP40
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	-5 ... 60 °C
CE ženklas (žr. deklaraciją)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS
Material cable sheath	TPE-U(PUR)
Kabelio apvalkalo spalva	pilkas
Material housing	POM
Korpuso spalva	Juodas
Material electrical contact	Vario lydinys Galvanizuota
Material insulation	PVC