 



# Kištukas NECU-S-M12G4-P1-Q6-IS

Gaminio numeris: 570955

FESTO

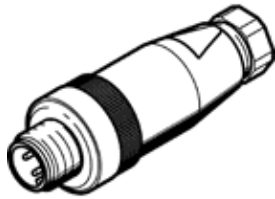

## Tech. Duomenys

Savybės	Reikšmė
Paremtas standartu	EN 61076-2-101 EN 61984
Prijungimo dažnis	50
Montavimo pozicija	Bet koks
Produkto svoris	18 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	apvalus
Electrical connection 1, connection type	Kištukas
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 1, number of pins/wires	4
Electrical connection 1, type of mounting	Screw-type lock with hex A/F 18 mm and longitudinal knurl
Electrical connection 2, connection type	Kabelis
Electrical connection 2, connection technology	Įsuktas terminalas
Nominalus DC įtampos lygis	0 ... 30 V
Leistina srovės apkrova prie 40°C	4 A
Atsparumas smūgiams	2,5 kV
Kabelio prijungimas	Pg7
Leistinas kabelio skersmuo	2,5 ... 2,9 mm
Gnybto skerspjūvis	0,14 ... 0,5 mm <sup>2</sup>
Apsaugos klasė	IP65 IP67
Aplinkos temperatūra	-25 ... 85 °C
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS
Užterštumo laipsnis	3
Material housing	PA
Material of union nut	PA
Material electrical contact	Žalvaris Balta bronz padengta