
 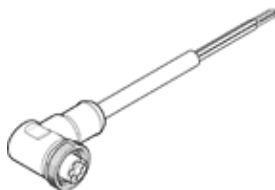


Maitinimo tinklo išėjimo lizdas

NEBU-G78W5-K-2-N-LE5

Gaminio numeris: 573855

FESTO



Tech. Duomenys

Savybės	Reikšmė
Paremtas standartu	NFPA/T3.5.29 R1-2007
Cable identification	Without inscription label holder
Prijungimo dažnis	100
Produkto svoris	680 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	apvalus
Electrical connection 1, connection type	Kištuvo lizdas
Electrical connection 1, cable outlet	Angled
Electrical connection 1, note about the cable outlet	Cable outlet not according to industry standard. Matched with CPX protective hood.
Electrical connection 1, connection technology	G7/8 coded to NFPA/T3.5.29 R1-2007
Electrical connection 1, number of pins/wires	5
Electrical connection 1, occupied pins/wires	5
Electrical connection 1, type of mounting	Screw lock
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Kabelis
Electrical connection 2, connection technology	atviri laidai
Electrical connection 2, number of pins/wires	5
Electrical connection 2, occupied pins/wires	5
Nominalus DC įtampos lygis	0 ... 300 V
Nominalus AC įtampos lygis	0 ... 300 V
Leistina srovės apkrova prie 40°C	9 A
Atsparumas smūgiams	4 kV
Kabelio ilgis	2 m
Kabelio priedas	Standartas
Laido bandymo sąlygos	Bandytas pagal užklausimą
Bending radius, fixed cable installation	≥ 65 mm
Kabelio skersmuo	8,7 mm
Kabelio skersmens tolerancija	± 0,2 mm
Kabelio struktūra	5x1,5
Nominalus laidininko skerspjūvis	1,5 mm ²
Apsaugos klasė	IP65 IP67
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	-20 ... 80 °C
CE ženklas (žr. deklaraciją)	atitinka EU reikalavimus žemose įtampose
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS
Užterštumo laipsnis	3
Atsparumo korozijai klasė CRC	1 - Low corrosion stress
Material cable sheath	TPE-U(PUR)
Kabelio apvalkalo spalva	Juodas
Material housing	TPE-U(PUR)
Korpuso spalva	Juodas
Material screw-type lock	Nickel-plated brass
Material electrical contact	Brass, gold-plated