


# Pajungimo kabelis NEBC-S1G25-K-1.0-N-S1G25

Gaminio numeris: 8001374

FESTO

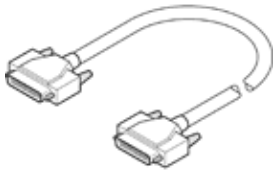

## Tech. Duomenys

Savybės	Reikšmė
Cable identification	Without inscription label holder
Elektrinis pajungimas	25-galvučių Tiesus kištukas Sub-D / Sub-D
Electrical connection 1, function	Field device side
Electrical connection 1, design	kampinis
Electrical connection 1, connection type	Kištukas
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	25
Electrical connection 1, occupied pins/wires	25
Electrical connection 1, type of mounting	2 screws 4-40 UNC
Electrical connection 2, function	Controller side
Electrical connection 2, design	kampinis
Electrical connection 2, connection type	Kištuko lizdas
Electrical connection 2, cable outlet	Tiesus
Electrical connection 2, connection technology	Sub-D
Electrical connection 2, number of pins/wires	25
Electrical connection 2, occupied pins/wires	25
Electrical connection 2, type of mounting	2 screws 4-40 UNC
Nominali darbinė nuolatinė įtampa	24 V
Leistina srovės apkrova prie 40°C	1 A
Kabelio ilgis	1 m
Kabelio priedas	Standartas
Kabelio skersmuo	7 mm
Kabelio struktūra	Ekranuotas
Apsaugos klasė	IP40
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	0 ... 70 °C
CE ženklas (žr. deklaraciją)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364 zone III
Informacija	atitinka RoHS
Atsparumo korozijai klasė CRC	0 - No corrosion stress
Material cable sheath	PVC
Kabelio apvalkalo spalva	pilkas
Korpuso spalva	pilkas