


Pajungimo kabelis NEBV-

Gaminio numeris: 8003577

FESTO

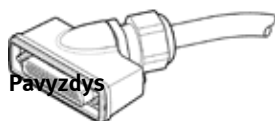

Tech. Duomenys

Pilnas duomenų lapas- atskiros reikšmės priklauso nuo Jūsų konfigūracijos.

Savybės	Reikšmė
Papildomos funkcijos	Laikymo srovės sumažėjimas Protective circuit
Cable identification	Without inscription label holder
Prijungimo dažnis	50
Electrical connection 1, function	Field device side
Electrical connection 1, design	kampinis
Electrical connection 1, connection type	Kištuvo lizdas Socket, slim
Electrical connection 1, cable outlet	Tiesus Angled
Electrical connection 1, connection technology	Connection pattern ZC, self-tapping screw Connection pattern ZC, metric screw Plug pattern type C to EN 175301-803 Sub-D
Electrical connection 1, number of pins/wires	2 25 4 44
Electrical connection 2, function	Controller side
Electrical connection 2, design	kampinis apvalus
Electrical connection 2, connection type	Kabelis Kištukas
Electrical connection 2, cable outlet	Tiesus Angled
Electrical connection 2, connection technology	Connection pattern ZB, self-tapping screw M8x1, A-coded to EN 61076-2-104 atviri laidai
Electrical connection 2, number of pins/wires	2 25 3 44
Nominalus DC įtampos lygis	0 ... 230 V
Nominalus AC įtampos lygis	0 ... 230 V
Kabelio ilgis	0,5 ... 30 m
Kabelio priedas	Standartas Suitable for energy chains
Laido bandymo sąlygos	Bandytas pagal užklausimą
CE ženklas (žr. deklaracija)	atitinka EU-EMV reikalavimus atitinka EU reikalavimus žemose įtampose in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment To UK instructions for EMC To UK RoHS instructions

Savybės	Reikšmė
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS
Material cable sheath	PVC TPE-U(PUR)
Kabelio apvalkalo spalva	pilkas