


# Pajungimo kabelis

## NEBV-C1SW2L-P-K-10-N-LE2-S9

Gaminio numeris: 8032627

FESTO

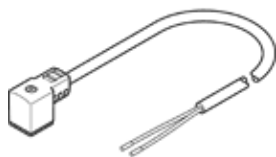

## Tech. Duomenys

Savybės	Reikšmė
Signal status display	LED geltonas
Papildomos funkcijos	Protective circuit
Cable identification	Without inscription label holder
Prijungimo dažnis	50
Produkto svoris	440 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	kampinis
Electrical connection 1, connection type	Socket, slim
Electrical connection 1, cable outlet	Angled
Electrical connection 1, note about the cable outlet	180° rotatable
Electrical connection 1, connection technology	Plug pattern type C to EN 175301-803
Electrical connection 1, number of pins/wires	4
Electrical connection 1, occupied pins/wires	2
Electrical connection 1, type of mounting	Elektromagnetiniame skirstytuve su M2.5 centriniu varžtu
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Kabelis
Electrical connection 2, connection technology	atviri laidai
Electrical connection 2, number of pins/wires	2
Electrical connection 2, occupied pins/wires	2
Nominalus DC įtampas lygis	20,4 ... 26,4 V
Nominali darbinė nuolatinė įtampa	24 V
Leistina srovės apkrova prie 40°C	6 A
Atsparumas smūgiams	2,4 kV
Apsaugotas nuo poliariškumo pakeitimo	bipolinis
Apsaugotas įžeminimas	Negalimas
Kabelio ilgis	10 m
Kabelio priedas	Standartas
Laido bandymo sąlygos	Bandytas pagal užklausimą
Bending radius, flexible cable installation	≥ 52 mm
Kabelio skersmuo	5,2 mm
Kabelio skersmens tolerancija	± 0,1 mm
Kabelio struktūra	2x0,75
Nominalus laidininko skerspjūvis	0,75 mm <sup>2</sup>
Apsaugos klasė	IP65 IP67
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	-20 ... 70 °C
Aplinkos temperatūra esant lankščiai kabelių instaliacijai	-5 ... 70 °C
CE ženklas (žr. deklaraciją)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS
Užterštumo laipsnis	3
Atsparumo korozijai klasė CRC	3 - High corrosion stress
Material cable sheath	PVC
Kabelio apvalkalo spalva	pilkas

Savybės	Reikšmė
Material housing	TPE-U(PU)
Korpuso spalva	Juodas
Material screws	Nerūdijantis plienas
Material seals	HNBR
Material electrical contact	Copper alloy, tinned
Material insulation	PVC