 



Pajungimo kabelis NEBV-Z4WA2L-R-E-0.2-N-Z1W2-S1

Gaminio numeris: 8047682

FESTO

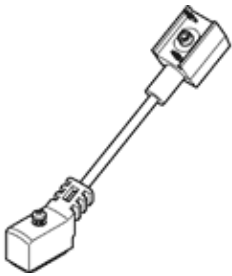

Tech. Duomenys

Savybės	Reikšmė
Signal status display	LED geltonas
Papildomos funkcijos	Laikymo srovės sumažėjimas Protective circuit
Cable identification	Without inscription label holder
Prijungimo dažnis	50
Produkto svoris	18 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	kampinis
Electrical connection 1, connection type	Kištuko lizdas
Electrical connection 1, cable outlet	Angled
Electrical connection 1, connection technology	Connection pattern ZC, metric screw
Electrical connection 1, number of pins/wires	2
Electrical connection 1, occupied pins/wires	2
Electrical connection 1, type of mounting	Elektromagnetiniame skirstytuve su M2 centriniu varžtu
Electrical connection 2, function	Controller side
Electrical connection 2, design	kampinis
Electrical connection 2, connection type	Kištukas
Electrical connection 2, cable outlet	Angled
Electrical connection 2, connection technology	Connection pattern ZB, self-tapping screw
Electrical connection 2, number of pins/wires	2
Electrical connection 2, occupied pins/wires	2
Electrical connection 2, type of mounting	Elektromagnetiniame skirstytuve su išsitraukiančiu varžtu
Nominalus DC įtampos lygis	20,4 ... 26,4 V
Nominali darbinė nuolatinė įtampa	24 V
Atsparumas smūgiams	2,4 kV
Apsaugotas nuo poliarizavimo pakeitimo	bipolinis
Apsaugotas įžeminimas	Negalimas
Kabelio ilgis	0,2 m
Kabelio priedas	Suitable for energy chains
Laido bandymo sąlygos	Bandymas pagal užklausimą
Bending radius, flexible cable installation	≥ 29 mm
Kabelio skersmuo	2,9 mm
Kabelio skersmens tolerancija	± 0,1 mm
Kabelio struktūra	2x0,14
Nominalus laidininko skerspjūvis	0,14 mm ²
Apsaugos klasė	IP65
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	-10 ... 50 °C
CE ženklas (žr. deklaraciją)	atitinka EU-EMV reikalvumus in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS
Užterštumo laipsnis	3
Atsparumo korozijai klasė CRC	3 - High corrosion stress

Savybės	Reikšmė
Material cable sheath	TPE-U(PUR)
Kabelio apvalkalo spalva	pilkas
Material housing	TPE-U(PU)
Korpuso spalva	Juodas
Material screws	Nerūdijantis plienas
Material electrical contact	Copper alloy, tinned
Material insulation	PP