
 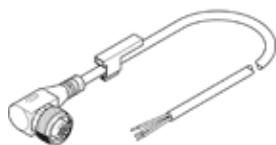


Pajungimo kabelis NEBB-M12W5-P-2.5-LE3

Gaminio numeris: 8066679

FESTO



Tech. Duomenys

| Savybės | Reikšmė |
|--|--|
| Atitinka standartus | Core colours and connection numbers to EN 60947-5-2 EN 61076-2-101 |
| Cable identification | With inscription label holder |
| Electrical connection 1, function | Field device side |
| Electrical connection 1, design | apvalus |
| Electrical connection 1, connection type | Kištuvo lizdas |
| Electrical connection 1, cable outlet | Angled |
| Electrical connection 1, connection technology | M12x1, A-coded in accordance with EN 61076-2-101 |
| Electrical connection 1, number of pins/wires | 5 |
| Electrical connection 1, occupied pins/wires | 3 |
| Electrical connection 1, type of mounting | Screw lock with A/F13 |
| Electrical connection 2, function | Controller side |
| Electrical connection 2, connection type | Kabelis |
| Electrical connection 2, connection technology | atvirai laidai |
| Electrical connection 2, number of pins/wires | 3 |
| Electrical connection 2, occupied pins/wires | 3 |
| Nominalus DC įtampos lygis | 0 ... 250 V |
| Nominalus AC įtampos lygis | 0 ... 250 V |
| Leistina srovės apkrova prie 40°C | 4 A |
| Atsparumas smūgiams | 2,5 kV |
| Kabelio ilgis | 2,5 m |
| Kabelio priedas | Statiniam panaudojimui |
| Laido bandymo sąlygos | Bandyamas pagal užklausimą |
| Bending radius, fixed cable installation | ≥ 12 mm |
| Kabelio skersmuo | 3,8 mm |
| Kabelio struktūra | 3x0,25 |
| Nominalus laidininko skerspjuvis | 0,25 mm ² |
| Laido galai | Sheath removed Cut off bluntly |
| Apsaugos klasė | IP65 IP68 IP69K |
| Note on degree of protection | Sumontuotas |
| Aplinkos temperatūra | -25 ... 70 °C |
| CE ženklas (žr. deklaraciją) | atitinka EU reikalavimus žemose įtampose in accordance with EU RoHS directive |
| UKCA marking (see declaration of conformity) | To UK instructions for electrical equipment To UK RoHS instructions |
| PWIS conformity | VDMA24364-B2-L |
| Švaros klasė | ISO class 4 |
| Informacija | atitinka RoHS |
| Užterštumo laipsnis | 3 |
| Atsparumo korozijai klasė CRC | 2 - Moderate corrosion stress |
| Material cable sheath | PVC |
| Kabelio apvalkalo spalva | pilkas |
| Material housing | TPE-U(PU) |

| Savybės | Reikšmė |
|-----------------------------|--------------------------|
| Korpuso spalva | Juodas |
| Material screw-type lock | Nickel-plated brass |
| Material seals | NBR |
| Material electrical contact | Gold-plated copper alloy |
| Material insulation | PVC |