


# Pajungimo kabelis NEBV-Q7G2-PD-0.1-N-LE2

Gaminio numeris: 8115892

FESTO

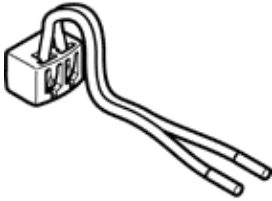

## Tech. Duomenys

Savybės	Reikšmė
Cable identification	Without inscription label holder
Prijungimo dažnis	20
Produkto svoris	0,5 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	kampinis
Electrical connection 1, connection type	Kištuvo lizdas
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	Connection pattern Q7
Electrical connection 1, number of pins/wires	2
Electrical connection 1, occupied pins/wires	2
Electrical connection 1, type of mounting	Plug-in
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Twin wire
Electrical connection 2, connection technology	atviri laidai
Electrical connection 2, number of pins/wires	2
Electrical connection 2, occupied pins/wires	2
Nominalus DC įtampas lygis	0 ... 30 V
Leistina srovės apkrova prie 40°C	0,3 A
Atsparumas smūgiams	1,2 kV
Apsaugotas nuo poliariškumo pakeitimo	Ne
Apsaugotas įžeminimas	Negalimas
Shielding	Ne
Nuoroda veikimui	Operate only with external power reduction
Kabelio ilgis	0,1 m
Kabelio priedas	Basic
Laido bandymo sąlygos	Bandytas pagal užklausimą
Bending radius, fixed cable installation	≥ 11 mm
Bending radius, flexible cable installation	≥ 16,5 mm
Kabelio skersmuo	1,1 mm
Kabelio struktūra	2x0,08
Nominalus laidininko skerspjūvis	0,08 mm <sup>2</sup>
Nominal conductor cross section (AWG)	AWG28
Laido galai	Galvanizuota
Apsaugos klasė	IP40
Aplinkos temperatūra	0 ... 50 °C
Saugojimo temperatūra	-20 ... 70 °C
CE ženklas (žr. deklaraciją)	in accordance with EU RoHS directive
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS
Atsparumo korozijai klasė CRC	0 - No corrosion stress
Material housing	PA - sustiprintas
Korpuso spalva	Juodas
Material electrical contact	Gold-plated copper alloy
Material insulation	PVC