


Set axial EAMM-A-L38-60RA

Numar piesa: 8197449

FESTO

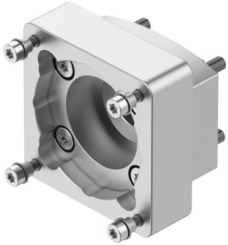

Fisa de date

Caracteristica	Valoare
Lungime nominala	36 mm...36 mm
Pozitie de instalare	orice
Turatie max.	8000 1/min...8000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...-25 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...-10 °C
Momentul de inertie al masei	3.2 kgmm ²
Cuplu transmisibil	4.4 Nm
Greutate produs	254 g...254 g
Cod de interfata actuator	L38
Codul interfetei motor In	60RA
Nota privind materialele	Conform RoHS