


Set axial EAMM-A-N38-60G-G2

Numar piesa: 8197462

FESTO

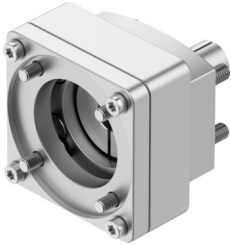

Fisa de date

Caracteristica	Valoare
Lungime nominala	41 mm...41 mm
Pozitie de instalare	orice
Turatie max.	8000 1/min...8000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...-25 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...-10 °C
Momentul de inertie al masei	14.5 kgmm ²
Cuplu transmisibil	16 Nm
Greutate produs	375 g...375 g
Cod de interfata actuator	N38
Codul interfetei motor In	60G
Nota privind materialele	Conform RoHS