


## Set axial EAMM-A-N48-87A

Numar piesa: 8197466

FESTO

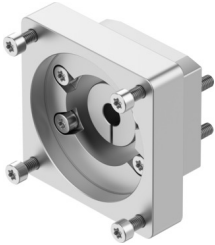

### Fisa de date

Caracteristica	Valoare
Lungime nominala	44 mm...44 mm
Pozitie de instalare	orice
Turatie max.	8000 1/min...8000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...-25 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...-10 °C
Momentul de inertie al masei	14.5 kgmm <sup>2</sup>
Cuplu transmisibil	12.5 Nm
Greutate produs	504 g...504 g
Cod de interfata actuator	N48
Codul interfetei motor In	87A
Nota privind materialele	Conform RoHS