


## Set axial EAMM-A-S95-120G

Numar piesa: 8197476

FESTO

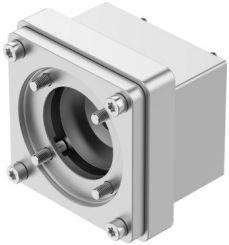

### Fisa de date

Caracteristica	Valoare
Lungime nominala	100.5 mm...100.5 mm
Pozitie de instalare	orice
Turatie max.	5500 1/min...5500 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...-25 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...-10 °C
Momentul de inertie al masei	128 kgmm <sup>2</sup>
Cuplu transmisibil	75 Nm
Greutate produs	4350 g...4350 g
Cod de interfata actuator	S95
Codul interfetei motor In	120G
Nota privind materialele	Conform RoHS