


## Set axial EAMM-A-S38-60P-G3

Numar piesa: 8197479

FESTO

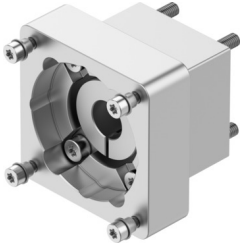

### Fisa de date

Caracteristica	Valoare
Lungime nominala	49 mm
Pozitie de instalare	orice
Turatie max.	8000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	5.87 kgmm <sup>2</sup>
Cuplu transmisibil	6.5 Nm
Greutate produs	290 g
Cod de interfata actuator	S38
Codul interfetei motor In	60P 60PA
Nota privind materialele	Conform RoHS