


# Set axial EAMM-A-S48-80P

Numar piesa: 8197480

FESTO

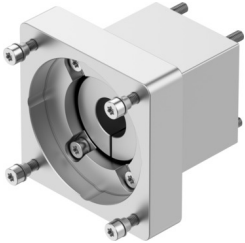

## Fisa de date

Caracteristica	Valoare
Lungime nominala	72 mm...72 mm
Pozitie de instalare	orice
Turatie max.	6000 1/min...6000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...-25 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...-10 °C
Momentul de inertie al masei	34.8 kgmm <sup>2</sup>
Cuplu transmisibil	17 Nm
Greutate produs	590 g...590 g
Cod de interfata actuator	S48
Codul interfetei motor In	80P 80PA 80RA
Nota privind materialele	Conform RoHS