


# Set axial EAMM-A-S48-60H-G3

Numar piesa: 8197482

FESTO

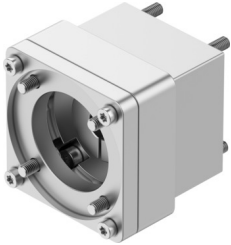

## Fisa de date

Caracteristica	Valoare
Lungime nominala	55.5 mm...55.5 mm
Pozitie de instalare	orice
Turatie max.	8000 1/min...8000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...-25 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...-10 °C
Momentul de inertie al masei	5.87 kgmm <sup>2</sup>
Cuplu transmisibil	12.5 Nm
Greutate produs	340 g...340 g
Cod de interfata actuator	S48
Codul interfetei motor In	60H
Nota privind materialele	Conform RoHS