


Set axial EAMM-A-S38-60RA-G2

Numar piesa: 8197484

FESTO

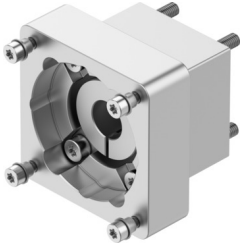

Fisa de date

Caracteristica	Valoare
Lungime nominala	49 mm...49 mm
Pozitie de instalare	orice
Turatie max.	8000 1/min...8000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...-25 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...-10 °C
Momentul de inertie al masei	5.87 kgmm ²
Cuplu transmisibil	6.5 Nm
Greutate produs	290 g...290 g
Cod de interfata actuator	S38
Codul interfetei motor In	60RA
Nota privind materialele	Conform RoHS