


## Set axial EAMM-A-D50-60H-S1-G2

Numar piesa: 8197491

FESTO

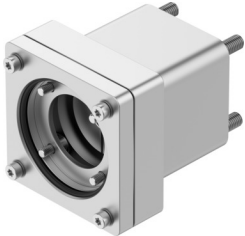

### Fisa de date

Caracteristica	Valoare
Lungime nominala	78 mm...78 mm
Pozitie de instalare	orice
Turatie max.	6000 1/min...6000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...-25 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP65
Temperatura ambianta	-10 °C...-10 °C
Momentul de inertie al masei	34.8 kgmm <sup>2</sup>
Cuplu transmisibil	21 Nm
Greutate produs	950 g...950 g
Cod de interfata actuator	D50
Codul interfetei motor In	60H
Nota privind materialele	Conform RoHS