


Set axial EAMM-A-D50-80P-S1-G2

Numar piesa: 8197494

FESTO

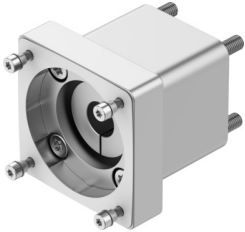

Fisa de date

Caracteristica	Valoare
Lungime nominala	78.5 mm...78.5 mm
Pozitie de instalare	orice
Turatie max.	6000 1/min...6000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...-25 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP65
Temperatura ambianta	-10 °C...-10 °C
Momentul de inertie al masei	34.8 kgmm ²
Cuplu transmisibil	21 Nm
Greutate produs	810 g...810 g
Cod de interfata actuator	D50
Codul interfetei motor In	80P 80PA 80RA
Nota privind materialele	Conform RoHS