


## Set axial EAMM-A-D32-60P-S1-G2

Numar piesa: 8197495

FESTO

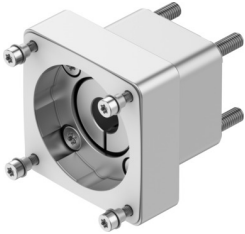

### Fisa de date

Caracteristica	Valoare
Lungime nominala	51 mm...51 mm
Pozitie de instalare	orice
Turatie max.	8000 1/min...8000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...-25 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP65
Temperatura ambianta	-10 °C...-10 °C
Momentul de inertie al masei	5.87 kgmm <sup>2</sup>
Cuplu transmisibil	6.5 Nm
Greutate produs	380 g...380 g
Cod de interfata actuator	D32
Codul interfetei motor In	60P 60PA
Nota privind materialele	Conform RoHS