


Set axial EAMM-A-D40-60P-S1-G2

Numar piesa: 8197497

FESTO

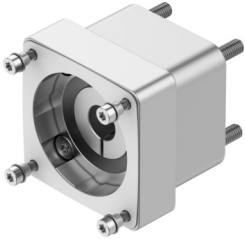

Fisa de date

Caracteristica	Valoare
Lungime nominala	52 mm...52 mm
Pozitie de instalare	orice
Turatie max.	8000 1/min...8000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...-25 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP65
Temperatura ambianta	-10 °C...-10 °C
Momentul de inertie al masei	5.87 kgmm ²
Cuplu transmisibil	12.5 Nm
Greutate produs	340 g...340 g
Cod de interfata actuator	D40
Codul interfetei motor In	60P 60PA
Nota privind materialele	Conform RoHS