


Set axial EAMM-A-D60-80G-G2

Numar piesa: 8199480

FESTO

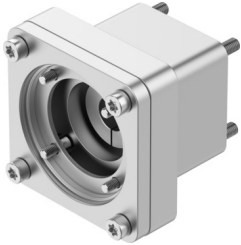

Fisa de date

Caracteristica	Valoare
Lungime nominala	77.4 mm...77.4 mm
Pozitie de instalare	orice
Turatie max.	6000 1/min...6000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...-25 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...-10 °C
Momentul de inertie al masei	34.8 kgmm ²
Cuplu transmisibil	21 Nm
Greutate produs	1500 g...1500 g
Cod de interfata actuator	D60 D60C
Codul interfetei motor In	80G
Nota privind materialele	Conform RoHS