


# Unitate de ghidare FEN-12/16-160-KF

Numar piesa: 8204029

FESTO

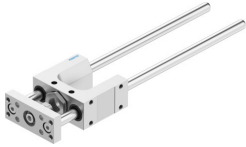

## Fisa de date

Caracteristica	Valoare
Dimensiune	12/16
Cursa	160 mm
Pozitie de instalare	orice
Ghidaj	Ghidaj cu bile de recirculare
Structura constructiva	Ghidaj
Protectie la explozie	Respectati informatiile din certificat
Conformitatea LABS	VDMA24364-B2-L
Temperatura ambianta	-20 °C...80 °C
Forta max. Fy	520 N
Forta max. Fy statica	830 N
Forta max. Fz	520 N
Forta max. Fz statica	830 N
Moment max. Mx	12 Nm
Moment max. Mx static	20 Nm
Max. Moment My	7 Nm
Moment My static max.	12 Nm
Moment max. Mz	7 Nm
Moment Mz static max.	12 Nm
Forta de deplasare	15 N
Masa in miscare	353 g
Greutate produs	621 g
Tipul de montare	cu filet interior
Nota privind materialele	Conform RoHS
Material element de ghidare	Otel calit
Material carcasa	Aliaj de aluminiu forjat, anodizat
Material placa de jug	Aliaj de aluminiu forjat, anodizat