


Prindere delicata HPSX-100-4-S-40-BU-RA50

Numar piesa: 8207884

FESTO

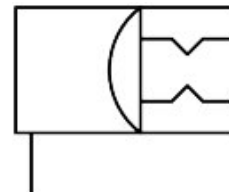

Fisa de date

Caracteristica	Valoare
Dimensiune	100
Cursa de lucru	30 mm...125 mm
Diametrul min. de prindere	80 mm
Diametru max. de prindere	110 mm
Tip de actionare	pneumatic
Pozitie de instalare	orice
Mod de functionare	cu dubla actiune
Functie gripper	Adaptiv
Numarul de degete de gripper	4
Structura constructiva	forma ajustata angajat prin frecare
Presiune de lucru	-0.085 MPa...0.02 MPa -0.85 bar...0.2 bar -12.325 psi...2.9 psi
Presiune de spargere capac	0.06 MPa 0.6 bar 8.7 psi
Frecventa de lucru max. dispozitiv de prindere	5 Hz
Mediu de operare	Aer comprimat conform ISO 8573-1:2010 [7:4:4]
Clasa de rezistenta la coroziune KBK	4 - Mediu coroziv deosebit de puternic
Conformitatea LABS	VDMA24364 zona III
Siguranta alimentara	vedeti informatii detaliate despre material
Temperatura ambianta	0 °C...60 °C
Rezistenta la vibratii	Testul aplicatiei de transport cu grad de inclinare 2 conform FN 942017-4 si EN 60068-2-6
Tip de protectie	IP69K
Forta totala de prindere	23 N
Greutate produs	632 g
Tipul de montare	dupa ISO 9409-1-50-4-M6
Conexiune pneumatica	G1/4
Nota privind materialele	Conform RoHS
Material adaptor	Ranforsat cu PA

Caracteristica	Valoare
Material suruburi	Otel inoxidabil
Material bac de gripper	VMQ (silicon), antistatic
Material capac	Ranforsat cu PA
Culoare	albastru
Duritate Shore	A 40 +5