


# Prindere delicata HPSX-40-2-S-40-BU-RA50

Numar piesa: 8207885

FESTO

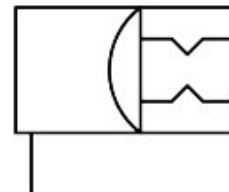

## Fisa de date

| Caracteristica                                 | Valoare                                                                                   |
|------------------------------------------------|-------------------------------------------------------------------------------------------|
| Dimensiune                                     | 40                                                                                        |
| Cursa de lucru                                 | 0 mm...55 mm                                                                              |
| Diametrul min. de prindere                     | 30 mm                                                                                     |
| Diametru max. de prindere                      | 55 mm                                                                                     |
| Tip de actionare                               | pneumatic                                                                                 |
| Pozitie de instalare                           | orice                                                                                     |
| Mod de functionare                             | cu dubla actiune                                                                          |
| Functie gripper                                | Adaptiv                                                                                   |
| Numarul de degete de gripper                   | 2                                                                                         |
| Structura constructiva                         | forma ajustata<br>angajat prin frecare                                                    |
| Presiune de lucru                              | -0.085 MPa...0.02 MPa<br>-0.85 bar...0.2 bar<br>-12.325 psi...2.9 psi                     |
| Presiune de spargere capac                     | 0.06 MPa<br>0.6 bar<br>8.7 psi                                                            |
| Frecventa de lucru max. dispozitiv de prindere | 5 Hz                                                                                      |
| Mediu de operare                               | Aer comprimat conform ISO 8573-1:2010 [7:4:4]                                             |
| Clasa de rezistenta la coroziune KBK           | 4 - Mediu coroziv deosebit de puternic                                                    |
| Conformitatea LABS                             | VDMA24364 zona III                                                                        |
| Siguranta alimentara                           | vedeti informatii detaliate despre material                                               |
| Temperatura ambianta                           | 0 °C...60 °C                                                                              |
| Rezistenta la vibratii                         | Testul aplicatiei de transport cu grad de inclinare 2 conform FN 942017-4 si EN 60068-2-6 |
| Tip de protectie                               | IP69K                                                                                     |
| Forta totala de prindere                       | 5 N                                                                                       |
| Greutate produs                                | 240 g                                                                                     |
| Tipul de montare                               | dupa ISO 9409-1-50-4-M6                                                                   |
| Conexiune pneumatica                           | G1/4                                                                                      |
| Nota privind materialele                       | Conform RoHS                                                                              |
| Material adaptor                               | Ranforsat cu PA                                                                           |

| Caracteristica          | Valoare                   |
|-------------------------|---------------------------|
| Material suruburi       | Otel inoxidabil           |
| Material bac de gripper | VMQ (silicon), antistatic |
| Material capac          | Ranforsat cu PA           |
| Culoare                 | albastru                  |
| Duritate Shore          | A 40 +5                   |