


Kit axial EAMM-A-D60-60G-S1-G3

Numar piesa: 8234789

FESTO

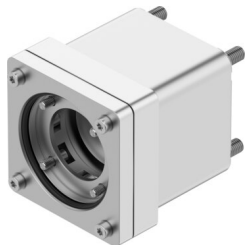

Fisa de date

Caracteristica	Valoare
Lungime nominala	76.5 mm
Pozitie de instalare	orice
Turatie max.	6000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP65
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	34.8 kgmm ²
Cuplu transmisibil	21 Nm
Greutate produs	1210 g
Cod de interfata actuator	D60
Codul interfetei motor In	60G
Nota privind materialele	Conform RoHS