 



Vod utičnice KMPPE-B-2,5

Broj artikla: 161879

FESTO

predgrađeno, za proporcionalni regulator pritiska.

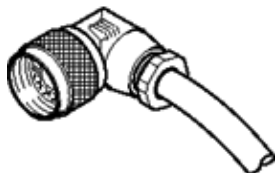

Tehnički podaci

Svojstvo	Vrednost
Odgovara standardu	DIN 47100
Cable identification	sa priborom
Frekvencija priključivanja	500
Težina proizvoda	243 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	okruglo
Electrical connection 1, connection type	Utičnica
Electrical connection 1, cable outlet	Angled
Electrical connection 1, connection technology	M16x0.75 to EN 61076-2-106
Electrical connection 1, number of pins/wires	8
Electrical connection 1, occupied pins/wires	8
Electrical connection 1, type of mounting	Screw lock
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Kabl
Electrical connection 2, connection technology	otvoreni kraj
Electrical connection 2, number of pins/wires	8
Electrical connection 2, occupied pins/wires	8
Područje pogonskog napona DC	0 ... 30 V
Strujna opteretivost kod 40°C	5 A
Čvrstoća na udarno naprezanje	0,6 kV
Dužina kabla	2,5 m
Svojstvo kabla	Standard
Uslovi ispitivanja kabla	Uslovi ispitivanja na zahtev
Prečnik kabla	6,8 mm
Struktura kabla	8x0,25 zaslonjeno
Nazivni presek provodnika	0,25 mm ²
Krajevi žica	Cut off bluntly
Mehanička zaštita	IP67
Note on degree of protection	u montiranom stanju
Temperatura okoline	-30 ... 80 °C
Temperatura okoline kod pokretnog postepenja kablova	-5 ... 70 °C
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B1/B2-L
Materijal - napomena	RoHS komformnost
Stepen zagađenja	1
Material cable sheath	PVC
Boja izolacije	sivo
Material housing	PA
Material screw-type lock	PA