


 
# Priključni kabl

## KMPYE-AIF-1-GS-GD-0,3

Broj artikla: 170239

FESTO

predugrađeno, za proporcionalni razvodnik.

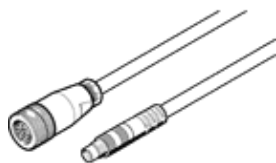

## Tehnički podaci

Svojstvo	Vrednost
Odgovara standardu	EN 61076-2-101
Dodatne funkcije	Product-specific pin allocation
Cable identification	sa priborom
Frekvencija priključivanja	500
Electrical connection 1, function	Field device side
Electrical connection 1, design	okruglo
Electrical connection 1, connection type	Utičnica
Electrical connection 1, cable outlet	Ravno
Electrical connection 1, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 1, number of pins/wires	4
Electrical connection 1, occupied pins/wires	4
Electrical connection 1, type of mounting	Screw-type lock with width across flats 18 and longitudinal knurl
Electrical connection 2, function	Controller side
Electrical connection 2, design	okruglo
Electrical connection 2, connection type	Utikači
Electrical connection 2, cable outlet	Ravno
Electrical connection 2, connection technology	M9x0,5
Electrical connection 2, number of pins/wires	7
Electrical connection 2, occupied pins/wires	6
Electrical connection 2, type of mounting	Screw lock
Područje pogonskog napona DC	0 ... 50 V
Strujna opteretivost kod 40°C	1 A
Čvrstoća na udarno naprezanje	2 kV
Dužina kabela	0,3 m
Svojstvo kabela	Suitable for energy chains
Uslovi ispitivanja kabela	Uslovi ispitivanja na zahtev
Bending radius, flexible cable installation	≥ 75 mm
Prečnik kabela	5,6 mm
Struktura kabela	8x0,24 zaslonjeno
Nazivni presek provodnika	0,24 mm <sup>2</sup>
Mehanička zaštita	IP65
Note on degree of protection	u montiranom stanju
Temperatura okoline	-25 ... 85 °C
Temperatura okoline kod pokretnog postepenja kablova	-5 ... 80 °C
PWIS conformity	VDMA24364-B2-L
Materijal - napomena	RoHS komformnost
Stepen zagađenja	1
Material cable sheath	TPE-U(PUR)
Boja izolacije	crno