


Ulazni modul CP-E16-M12X2-5POL

Broj artikla: 175561

FESTO

sa 16 ulaza

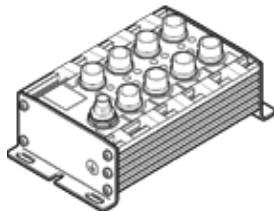

Tehnički podaci

Svojstvo	Vrednost
PWIS conformity	VDMA24364-B2-L
CE znak (vidi izjavu o usklađenosti)	prema EU-EMV-smernici prema EU-Ex-zaštita-smernica (ATEX) in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC To UK EX instructions To UK RoHS instructions
KC mark	KC-EMV
Dozvola	RCM Mark c UL us - Recognized (OL)
ATEX kategorija gasa	II 3G
ATEX kategorija prašine	II 3D
Odobrenje Eksplozivne zaštite izvan EU	EPL Dc (GB) EPL Gc (GB)
Ex vrsta zaštite od zapaljivanja - gas	Ex ec IIC T5 Gc X
Ex vrsta zaštite od zapaljivanja - prašina	Ex tc IIIC T80°C IP65 Dc X
Ex temperatura okoline	-5°C ≤ Ta ≤ +50°C