


# Modul za napajanje VABF-C8-12-P3A5-QX

Broj artikla: 1894888

Classic - nicht für Neukonstruktionen verwenden

Modern alternatives can be found by entering the first four characters of the type code in the search field.

FESTO

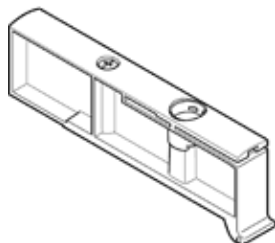

## Tehnički podaci

| Svojstvo                       | Vrednost                |
|--------------------------------|-------------------------|
| Pogonski pritisak              | < 8 bar                 |
| Klasa korozione otpornosti KBK | 0 - No corrosion stress |
| PWIS conformity                | VDMA24364-B1/B2-L       |
| Temperatura medijuma           | -5 ... 60 °C            |
| Temperatura okoline            | -5 ... 60 °C            |
| Težina proizvoda               | 13,8 g                  |
| Pneumatski priključak 1        | pripremljeno za uložak  |
| Materijal - napomena           | RoHS komfornost         |
| Material housing               | PA ojačan               |