

 

Prigušivač zvuka U-1/2

Broj artikla: 2310

★ Kernprogramm

FESTO

For reducing noise and avoiding contamination at the exhaust ports of pneumatic components.

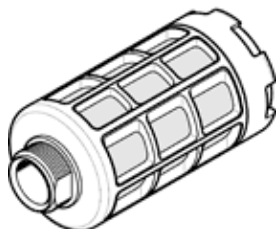

Tehnički podaci

Svojstvo	Vrednost
Položaj ugradnje	proizvoljno
Operating pressure MPa	0 ... 1 MPa
Pogonski pritisak	0 ... 10 bar
Protok prema atmosferi	10.300 l/min
Pogonski medijum	Kompresovani vazduh prema ISO 8573-1:2010 [7:-:-]
Napomena o mediju pogona i upravljanja	Moguć nauljeni pogon
PWIS conformity	VDMA24364-B1/B2-L
Nivo zvučnog pritiska	82 dB(A)
Temperatura okoline	-10 ... 70 °C
Težina proizvoda	58,2 g
Pneumatski priključak	G1/2
Material of silencer insert	PE
Materijal - napomena	RoHS komformnost