


Exhaust protection VABD-D3-SN-N12

Broj artikla: 3535104

FESTO

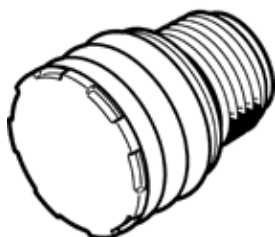

Tehnički podaci

Svojstvo	Vrednost
Položaj ugradnje	proizvoljno
Operating pressure MPa	0 ... 1,2 MPa
Pogonski pritisak	0 ... 12 bar
Pogonski medijum	Kompresovani vazduh prema ISO 8573-1:2010 [7::-]
PWIS conformity	VDMA24364 zone III
Mehanička zaštita	IP65
Temperatura okoline	-50 ... 60 °C
Vrsta pričvršćenja	navojno sa spoljašnjim navojem
Materijal - napomena	RoHS komformnost
Material seals	EPDM
Material vent screw	PA