

# Spojni vod


## NEBM-L5G18-E-10-N-LE18

Broj artikla: 4977494

Komponenta koja će prestati da se proizvodi

Komponenta se više ne proizvodi. Isporučuje se do 2026. Vidi Support Portal za alternativni proizvod.

FESTO

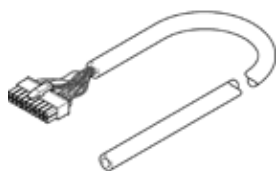

## Tehnički podaci

Svojstvo	Vrednost
Cable identification	Without inscription label holder
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utičnica
Electrical connection 1, cable outlet	Ravno
Electrical connection 1, connection technology	Pin allocation L5
Electrical connection 1, number of pins/wires	18
Electrical connection 1, occupied pins/wires	18
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Kabl
Electrical connection 2, connection technology	otvoreni kraj
Electrical connection 2, number of pins/wires	18
Electrical connection 2, occupied pins/wires	18
Područje pogonskog napona DC	0 ... 30 V
Područje pogonskog napona AC	0 ... 30 V
Strujna opteretivost kod 40°C	5 A
Čvrstoća na udarno naprezanje	1,5 kV
Dužina kabla	10 m
Svojstvo kabla	prikladno za energetske lanac
Uslovi ispitivanja kabla	Uslovi ispitivanja na zahtev
Bending radius, fixed cable installation	≥ 26 mm
Bending radius, flexible cable installation	≥ 43 mm
Prečnik kabla	8,5 mm
Struktura kabla	18x0,25
Nazivni presek provodnika	0,25 mm <sup>2</sup>
Krajevi žica	Cut off bluntly
Mehanička zaštita	IP20
Note on degree of protection	IP65 for mounting in terminal boxes
Temperatura okoline	-40 ... 80 °C
Temperatura okoline kod pokretnog postepenja kablova	-40 ... 80 °C
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Materijal - napomena	RoHS komfornost
Stepen zagađenja	3
Klasa korozione otpornosti KBK	0 - No corrosion stress
Material cable sheath	TPE-U(PUR)
Boja izolacije	sivo
Material housing	PA
Boja kućišta	crno
Material insulation	TPE-E