


# Vod upravljanja

## NEBC-S2G36-K-0.5-N-C2W36-S7

Broj artikla: 5105646

FESTO

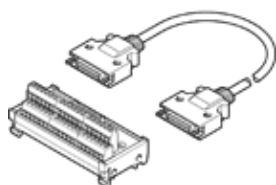

## Tehnički podaci

Svojstvo	Vrednost
Cable identification	Without inscription label holder
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utikači
Electrical connection 1, cable outlet	Ravno
Electrical connection 1, connection technology	SCSI
Electrical connection 1, number of pins/wires	36
Electrical connection 1, occupied pins/wires	36
Electrical connection 2, function	Controller side
Electrical connection 2, design	ugaono
Electrical connection 2, connection type	Terminal strip
Electrical connection 2, cable outlet	Ravno
Electrical connection 2, connection technology	Vijčana stezaljka
Electrical connection 2, number of pins/wires	36
Electrical connection 2, occupied pins/wires	36
Electrical connection 2, type of mounting	On H-rail
Područje pogonskog napona DC	0 ... 30 V
Područje pogonskog napona AC	0 ... 30 V
Strujna opteretivost kod 40°C	1,5 A
Čvrstoća na udarno naprezanje	0,5 kV
Dužina kabla	0,5 m
Svojstvo kabla	Standard
Bending radius, fixed cable installation	≥ 74 mm
Bending radius, flexible cable installation	≥ 110 mm
Prečnik kabla	7,4 mm
Struktura kabla	18x2x0,09
Nazivni presek provodnika	0,09 mm <sup>2</sup>
Mehanička zaštita	IP20
Note on degree of protection	u montiranom stanju
Temperatura okoline	-40 ... 80 °C
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364 zone III
Materijal - napomena	RoHS komformnost
Stepen zagađenja	1
Klasa korozione otpornosti KBK	0 - No corrosion stress
Material cable sheath	PVC
Boja izolacije	crno
Material housing	PA PBT
Boja kućišta	zeleno crno
Material insulation	PVC