

# Priključni kabl

## KMP6-25P-20-2,5


Broj artikla: 530046

Classic - nicht für Neukonstruktionen verwenden

za ventilski blok CPA-SC, sa Sub-D utikačem 25-polnim za 20 svitaka, 2, 5 m dug.

Modern alternatives can be found by entering the first four characters of the type code in the search field.

FESTO

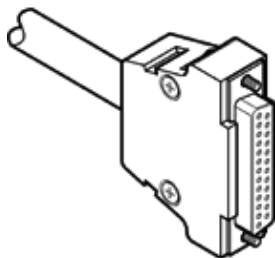

## Tehnički podaci

Svojstvo	Vrednost
Odgovara standardu	DIN 41652
Cable identification	Without inscription label holder
Frekvencija priključivanja	50
Težina proizvoda	432 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utičnica
Electrical connection 1, cable outlet	Ravno
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	25
Electrical connection 1, occupied pins/wires	25
Electrical connection 1, type of mounting	2 screws 4-40 UNC
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Kabl
Electrical connection 2, connection technology	otvoreni kraj
Electrical connection 2, number of pins/wires	25
Electrical connection 2, occupied pins/wires	25
Područje pogonskog napona DC	0 ... 30 V
Nazivni pogonski napon DC	24 V
Strujna opteretivost kod 40°C	2,8 A
Čvrstoća na udarno naprezanje	1 kV
Dužina kabla	2,5 m
Svojstvo kabla	Standard
Uslovi ispitivanja kabla	Uslovi ispitivanja na zahtev
Bending radius, fixed cable installation	≥ 103 mm
Bending radius, flexible cable installation	≥ 103 mm
Prečnik kabla	10,3 mm
Odstupanje prečnika kabla	± 0,25 mm
Struktura kabla	20x0,25+5x0,34
Nazivni presek provodnika	0,25 mm <sup>2</sup> 0,34 mm <sup>2</sup>
Krajevi žica	Cut off bluntly
Mehanička zaštita	IP40
Note on degree of protection	u montiranom stanju
Temperatura okoline	-25 ... 70 °C
Temperatura okoline kod pokretnog postepenja kablova	-5 ... 70 °C
Temperatura ležaja	-25 ... 75 °C
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Materijal - napomena	RoHS komformnost

Svojstvo	Vrednost
Stepen zagađenja	2
Material cable sheath	PVC
Boja izolacije	sivo
Material housing	PBT ojačan
Boja kućišta	sivo
Material screw-type lock	Nickel-plated brass
Material electrical contact	Gold-plated copper alloy