

Multipol CPV14-VI-P2-1/8-C


Broj artikla: 539498

Classic - nicht für Neukonstruktionen verwenden

za ventilski blok CPV.

Modern alternatives can be found by entering the first four characters of the type code in the search field.

FESTO

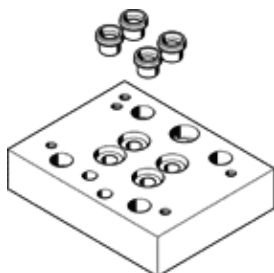

Tehnički podaci

Svojstvo	Vrednost
CE znak (vidi izjavu o usklađenosti)	prema EU-Ex-zaštita-smernica (ATEX)
UKCA marking (see declaration of conformity)	To UK EX instructions To UK RoHS instructions
Odobrenje Eksplozivne zaštite izvan EU	EPL Db (GB) EPL Db (IEC-EX) EPL Dc (IEC-EX) EPL Gb (GB) EPL Gb (IEC-EX) EPL Gc (IEC-EX)
Mesto izdavanja sertifikata	IECEx TUR 12.0002X TÜV 06 ATEX 7334 X TÜV 21 UKEX 7013 X
ATEX kategorija gasa	II 2G
ATEX kategorija prašine	II 2D
Ex vrsta zaštite od zapaljivanja - gas	Ex eb IIC Gb
Ex vrsta zaštite od zapaljivanja - prašina	Ex tb IIIC Db
Ex temperatura okoline	-10°C ≤ Ta ≤ +60°C
Klasa korozijske otpornosti KBK	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Težina proizvoda	500 g
Materijal - napomena	RoHS komfornost Bez halogena Free of copper
Material seals	NBR
Material plate	Aluminijumska legura za kovanje