 



# Fieldbus adapter FBA-CO-SUB-9-M12

Broj artikla: 540324

FESTO

za spajanje na CANopen ili Device Net.

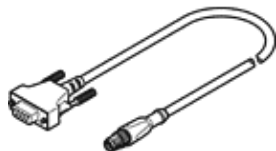

## Tehnički podaci

Svojstvo	Vrednost
Protokol	CANopen DeviceNet
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utičnica
Electrical connection 1, cable outlet	Ravno
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	9
Electrical connection 1, occupied pins/wires	6
Electrical connection 1, type of mounting	2x screw 4-40 UNC-2A
Electrical connection 2, function	Controller side
Electrical connection 2, design	okruglo
Electrical connection 2, connection type	Utikači
Electrical connection 2, cable outlet	Ravno
Electrical connection 2, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 2, number of pins/wires	5
Electrical connection 2, occupied pins/wires	5
Nazivni pogonski napon DC	24 V
Dužina kabla	0,1 m
Prečnik kabla	6,3 mm
Struktura kabla	4x0,34 zaslonjeno
Nazivni presek provodnika	0,34 mm <sup>2</sup>
Mehanička zaštita	IP67
Note on degree of protection	u montiranom stanju
Temperatura okoline	-5 ... 50 °C
PWIS conformity	VDMA24364 zone III
Materijal - napomena	RoHS komfornost
Klasa korozione otpornosti KBK	0 - No corrosion stress
Material cable sheath	TPE-U(PUR)