 



Pretvarač signala SVE4-HS-R-HM8-2N-M8

Broj artikla: 544219

FESTO

konvertuje analogni izlazni signal senzora u tačke prekidanja.

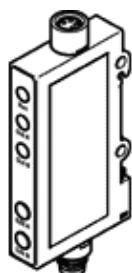

Tehnički podaci

Svojstvo	Vrednost
Dozvola	RCM Mark c UL us - Listed (OL)
UL-temperatura okoline	-20 ... 60 °C
CE znak (vidi izjavu o usklađenosti)	prema EU-EMV-smernici in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC To UK RoHS instructions
Materijal - napomena	RoHS komformnost
Signalno područje	za senzor pozicije SMH-S1-HG
Temperatura okoline	-20 ... 70 °C
Digitalni izlaz	2xNPN
Sklopna funkcija	slobodno se programira
Funkcija sklopnog elementa	prekidač
Otpornost na kratak spoj	u taktu
Otpornost na preopterećenje	postoji
Područje pogonskog napona DC	10 ... 30 V
Electrical connection 1, connection type	Utičnica
Electrical connection 1, connection technology	M8x1, A-coded to EN 61076-2-104
Electrical connection 1, number of pins/wires	4
Electrical connection 1, type of mounting	Screw lock
Electrical connection 2, connection type	Utikači
Electrical connection 2, connection technology	M8x1, A-coded to EN 61076-2-104
Electrical connection 2, number of pins/wires	4
Electrical connection 2, type of mounting	Screw lock
Težina proizvoda	19 g
Material housing	ABS
Mogućnosti podešavanja	Teach-In
Mehanička zaštita	IP65
Klasa korozione otpornosti KBK	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L