

Vod enkodera

 

NEBM-M12G8-E-10-S1G9

Broj artikla: 550749

★ Kernprogramm

odgovara za koračni motor EMMS-ST...

FESTO

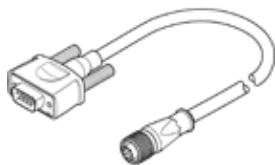

Tehnički podaci

| Svojstvo | Vrednost |
|--|--|
| Cable identification | Without inscription label holder |
| Electrical connection 1, function | Field device side |
| Electrical connection 1, design | okruglo |
| Electrical connection 1, connection type | Utičnica |
| Electrical connection 1, cable outlet | Ravno |
| Electrical connection 1, connection technology | M12x1, A-coded in accordance with EN 61076-2-101 |
| Electrical connection 1, number of pins/wires | 8 |
| Electrical connection 1, occupied pins/wires | 8 |
| Electrical connection 2, function | Controller side |
| Electrical connection 2, design | ugaono |
| Electrical connection 2, connection type | Utikači |
| Electrical connection 2, cable outlet | Ravno |
| Electrical connection 2, connection technology | Sub-D |
| Electrical connection 2, number of pins/wires | 9 |
| Electrical connection 2, occupied pins/wires | 8 |
| Područje pogonskog napona DC | 0 ... 30 V |
| Nazivni pogonski napon DC | 24 V |
| Područje pogonskog napona AC | 0 ... 30 V |
| Nazivni pogonski napon AC | 24 V |
| Dužina kabla | 10 m |
| Svojstvo kabla | Suitable for energy chains |
| Bending radius, flexible cable installation | >= 49 mm |
| Prečnik kabla | 6,5 mm |
| Struktura kabla | 4x2x0,14 zaslonjeno |
| Nazivni presek provodnika | 0,14 mm ² |
| Mehanička zaštita | IP65 |
| Note on degree of protection | IP30 for plug connector Sub-D u montiranom stanju |
| Temperatura okoline | -40 ... 70 °C |
| Temperatura okoline kod pokretnog postepenja kablova | -40 ... 70 °C |
| CE znak (vidi izjavu o usklađenosti) | in accordance with EU RoHS directive |
| UKCA marking (see declaration of conformity) | To UK RoHS instructions |
| PWIS conformity | VDMA24364-B2-L |
| Materijal - napomena | RoHS komformnost |
| Material cable sheath | TPE-U(PUR) |
| Boja izolacije | sivo |