 



Krajnja ploča VMPAL-EPL-SD44-IP40

Broj artikla: 560941

FESTO

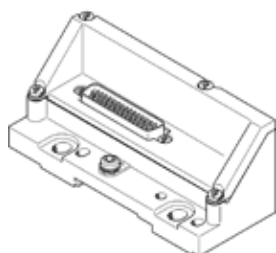

Tehnički podaci

Svojstvo	Vrednost
Širina	43 mm
Dužina	107,3 mm
Maks. broj ventilskih mesta	32
Struktura ventilskog bloka	Valve sizes can be mixed
Maksimalni broj elektromagnetnih kalema	32
Operating pressure MPa	-0,09 ... 1 MPa
Pogonski pritisak	-0,9 ... 10 bar
Pilot pressure MPa	0,3 ... 0,8 MPa
Pritisak upravljanja	3 ... 8 bar
Nazivni pogonski napon DC	24 V
Klasa korozione otpornosti KBK	3 - High corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Mehanička zaštita	IP40
Note on degree of protection	u montiranom stanju
Temperatura okoline	-5 ... 50 °C
Težina proizvoda	190 g
Electrical connection 1, function	Multipol
Electrical connection 1, connection type	Utikači
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	44
Materijal - napomena	RoHS komformnost
Material end plate	Aluminijumski odlivak PA ojačan