


# Pokrivna ploča VABB-L1-10-W

Broj artikla: 566495

★ Kernprogramm

FESTO

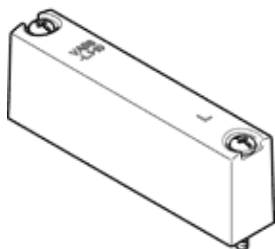

## Tehnički podaci

Svojstvo	Vrednost
Mera mreže	10,5 mm
Operating pressure MPa	-0,09 ... 1 MPa
Pogonski pritisak	-0,9 ... 10 bar
Dozvola	RCM Mark c UL us - Recognized (OL)
Klasa korozione otpornosti KBK	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Težina proizvoda	24 g
Materijal - napomena	RoHS komfornost
Material cover plate	PA