


Vod utičnice

NEBV-H1G2-KN-2.5-N-LE2

Broj artikla: 566656

★ Kernprogramm

FESTO

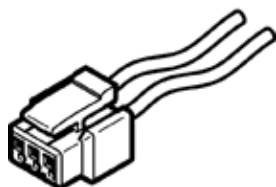

Tehnički podaci

Svojstvo	Vrednost
Cable identification	Without inscription label holder
Položaj ugradnje	proizvoljno
Težina proizvoda	17 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utičnica
Electrical connection 1, cable outlet	Ravno
Electrical connection 1, connection technology	Connection pattern H
Electrical connection 1, number of pins/wires	3
Electrical connection 1, occupied pins/wires	2
Electrical connection 1, type of mounting	Snap-in locking
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	2 single wires
Electrical connection 2, connection technology	otvoreni kraj
Electrical connection 2, number of pins/wires	2
Electrical connection 2, occupied pins/wires	2
Područje pogonskog napona DC	0 ... 60 V
Strujna opteretivost kod 40°C	3 A
Dužina kabela	2,5 m
Svojstvo kabela	Standard
Prečnik kabela	1,3 mm
Struktura kabela	2x0,14
Nazivni presek provodnika	0,14 mm ²
Krajevi žica	Cut off bluntly
Mehanička zaštita	IP40
Note on degree of protection	u montiranom stanju
Temperatura okoline	-5 ... 60 °C
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Materijal - napomena	RoHS komformnost
Material housing	POM
Boja kućišta	crno
Material electrical contact	Bakarna legura pocinkovano
Material insulation	PVC