


# Vod utičnice

## NEBV-H1G2-P-0.5-N-LE2

Broj artikla: 566658

★ Kernprogramm

FESTO

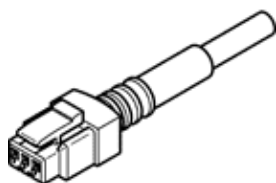

## Tehnički podaci

Svojstvo	Vrednost
Cable identification	Without inscription label holder
Položaj ugradnje	proizvoljno
Težina proizvoda	8 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utičnica
Electrical connection 1, cable outlet	Ravno
Electrical connection 1, connection technology	Connection pattern H
Electrical connection 1, number of pins/wires	3
Electrical connection 1, occupied pins/wires	2
Electrical connection 1, type of mounting	Snap-in locking
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Kabl
Electrical connection 2, connection technology	otvoreni kraj
Electrical connection 2, number of pins/wires	2
Electrical connection 2, occupied pins/wires	2
Područje pogonskog napona DC	0 ... 60 V
Strujna opteretivost kod 40°C	3 A
Dužina kabla	0,5 m
Svojstvo kabla	Za statičke namene
Prečnik kabla	3,4 mm
Struktura kabla	2x0,14
Nazivni presek provodnika	0,14 mm <sup>2</sup>
Krajevi žica	Sheath removed Cut off bluntly
Mehanička zaštita	IP40
Note on degree of protection	u montiranom stanju
Temperatura okoline	-5 ... 60 °C
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Materijal - napomena	RoHS komfornost
Material cable sheath	TPE-U(PUR)
Boja izolacije	sivo
Material housing	POM
Boja kućišta	crno
Material electrical contact	Bakarna legura pocinkovano
Material insulation	PVC