


# Prigušivač zvuka U-3/4-B-NPT

Broj artikla: 566823

FESTO

For reducing noise and avoiding contamination at the exhaust ports of pneumatic components.

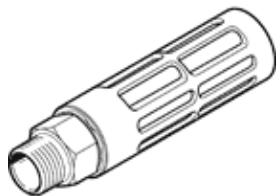

## Tehnički podaci

Svojstvo	Vrednost
Položaj ugradnje	proizvoljno
Operating pressure for entire temperature range	0 ... 1 MPa
Pogonski pritisak kompletnog temperaturnog područja	0 ... 10 bar
Operating pressure for entire temperature range	0 ... 145 psi
Protok prema atmosferi	11.834 l/min
Pogonski medijum	Kompresovani vazduh prema ISO 8573-1:2010 [7:-:-]
Napomena o mediju pogona i upravljanja	Moguć nauljeni pogon
Klasa korozione otpornosti KBK	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Nivo zvučnog pritiska	81 dB(A)
Temperatura okoline	-10 ... 70 °C
Težina proizvoda	128 g
Pneumatski priključak	3/4 NPT
Material of silencer insert	PE
Material of threaded plug	Aluminijum
Materijal - napomena	RoHS komfornost
Material housing	Aluminijum